



RONDELLE RESSORT DIN ISO 10069-2

RONDELLE ENTRETOISE

2441.3.

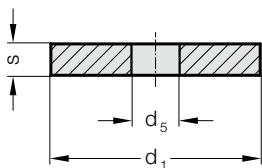

Exemple de montage

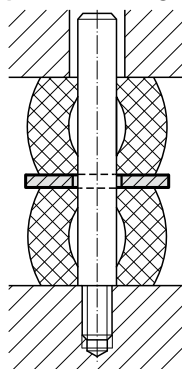

2441.3. Rondelle ressort DIN ISO 10069-2

ø du ressort	16	20	25	32	40	50	63	80	100	125
d ₁	20	25	30	40	50	60	80	100	120	150
d ₅	6,5	8,5	10,5	13,5	13,5	16,5	16,5	20,5	20,5	26
s	4	4	5	5	5	6	6	8	8	8


Matière :

Laiton


Exemple de commande :

Rondelle ressort DIN ISO 10069-2	=	2441.3.
Diamètre de ressort ø du ressort	50 mm =	050
N° de commande	=	2441.3. 050

244.4.

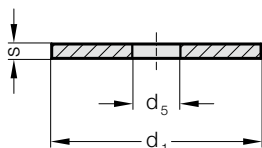

Exemple de montage

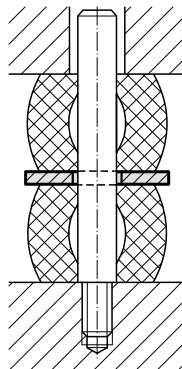

244.4. Rondelle entretoise

ø du ressort	16	20	25	32	40	50	63	80	100	125
d ₁	20	26	32	40	50	60	80	100	120	150
d ₅	6,5	8,5	10,5	13,5	13,5	16,5	16,5	20,5	20,5	26
s	1	1,5	2	2,5	2,5	3	3	4	4	5

Matière :

St 37

Exemple de commande :

Rondelle entretoise	=	244.4.
Diamètre de ressort ø du ressort	50 mm =	050
N° de commande	=	244.4. 050