


BOHRBUCHSE OHNE BUND, DIN 179 FORM A

277.

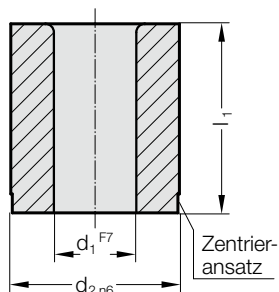

Werkstoff:

Einsatzstahl
Härte 740 ± 40 HV 10

Ausführung:

Durchmesser d_1 und d_2 geschliffen.

Andere Längen und Durchmesser auf Anfrage.

277. Bohrbuchse ohne Bund, DIN 179 Form A

d_1	d_2	Stufung	l_1	6	8	9	10	12	16	20	25	28	30	36	45	56	67
0,9 - 1	3	0.1		●		●											
1,1 - 1,8	4	0.1		●		●											
1,9 - 2,6	5	0.1		●		●											
2,7 - 3,3	6	0.1			●			●	●								
3,4 - 4	7	0.1			●			●	●								
4,1 - 5	8	0.1			●			●	●								
5,1 - 6	10	0.1					●		●	●							
6,1 - 8	12	0.1					●		●	●							
8,1 - 10	15	0.1						●	●	●		●					
10,1 - 12	18	0.1						●	●	●		●					
12,1 - 15	22	0.1							●	●		●		●			
15,5 - 18	26	0.5							●	●		●		●			
18,5 - 22	30	0.5								●		●		●	●		
22,5 - 26	35	0.5								●		●		●	●		
26,5 - 30	42	0.5									●	●		●	●	●	
30,5 - 35	48	0.5									●	●		●	●	●	
35,5 - 42	55	0.5										●		●	●	●	●
42,5 - 48	62	0.5											●	●	●	●	●

Bestell-Beispiel:

Bohrbuchse ohne Bund, DIN 179 Form A = 277.1.
 Führungsdurchmesser d_1 12.1 mm = 1210.
 Länge l_1 16 mm = 016
 Bestell-Nummer = 277.1. 1210.016