

# 符合DIN 59350带有加工余量的精密扁钢和精密方钢

材料:  
1.2343 / X 37 CrMoV 5-1  
热锻模钢


2923.2343.



我们为您提供  
**BÖHLER**  
原装质量

结构:  
厚度已精磨, 宽度已打磨或铣削, 长度已加工

说明:  
● = 适用于 500 mm 和 1000 mm 长度  
○ = 仅适用于 500 mm 长度  
■ = 仅适用于 1000 mm 长度

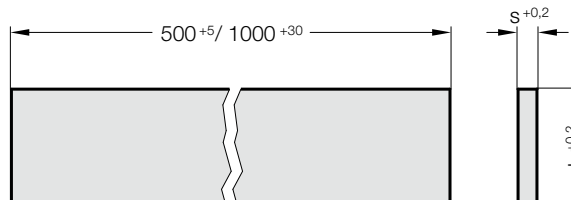

## 2923.2343. 符合DIN 59350带有加工余量的精密扁钢和精密方钢

s	4.2	5.2	6.2	8.2	10.4	12.4	15.4	16.4	20.4	25.4	30.4	32.4	40.4	50.4	60.4	80.4	100.4
b																	
10.3	○	○	○	○													
10.4					○												
12.4						○											
15.3	○	○	○	○	○	○											
15.4							○										
20.3	○	○	○	●	●	●	●	■									
20.4									●								
25.3	○	○	○	●	●	●	●	■	●								
25.4										●							
30.3	○	○	○	●	●	●	●		●	●							
30.4											●						
32.3								■									
40.3	○	○	○	●	●	●	●	■	●	●	●	■					
40.4													●				
50.3	○	○	○	●	●	●	●	■	●	●	●	■	●				
50.4														●			
60.3	○	○	○	●	●	●	●		●	●	●		●	●			
60.4															●		
63.3												■					
80.3	○	○	○	●	●	●	●	■	●	●	●	■	●	●	■		
80.4																■	
100.3	○	○	○	●	●	●	●	■	●	●	●	■	●	●	■	■	
100.4																	■
125.3				■	■	■	■	■	●	●	●	■	●	●	■	■	■
150.3				■	■	■	■	■	●	●	●	■	●	●	■	■	■
200.3				■	■	■	■	■	●	●	●	■	●	●	■	■	■

### 订购示例:

符合DIN 59350带有加工余量的精密扁钢和精密方钢	=	2923.2343.
宽 B	20.3 mm =	020.
厚度 S	4.2 mm =	004.
长度 L	500 mm =	0500
订购编号	=	2923.2343. 020. 004. 0500